

# UJGMPUCRY

---

## Base Product



Ultra Low Loss ULL TeraSPEED® MPO (Unpinned) to Unconnectorized Pre-terminated Trunk Cable, MPO12, 1728-Fiber, LSZH/Riser, 12-fiber Rollable Ribbon Central Tube

## Product Classification

<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly


## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Green
<b>Construction Type</b>	Rollable ribbon
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-12/APC Female
<b>Interface, Connector B</b>	Unterminated
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	1728

## Dimensions

<b>Breakout Length</b>	45 in
<b>Cable Assembly Length Range (m)</b>	6 – 609
<b>Cable Assembly Length Range (ft)</b>	20 – 999

## Ordering Tree

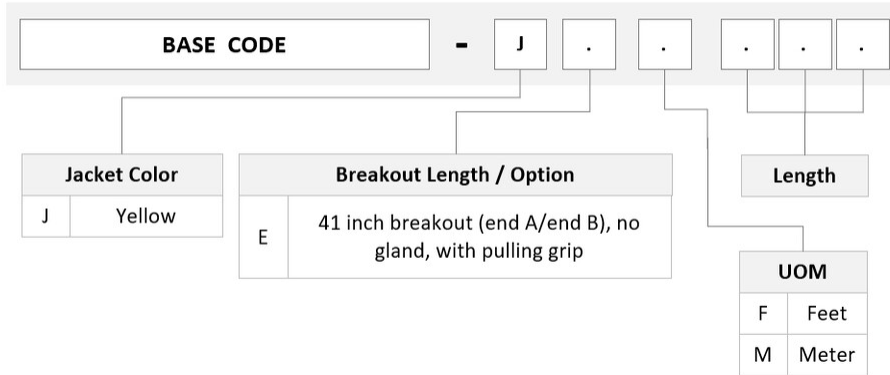

## Regulatory Compliance/Certifications

### Agency

ANATEL

ISO 9001:2015



### Classification

Compliant

Designed, manufactured and/or distributed under this quality management system

## Included Products

- |  |   |   |
|--|---|---|
| 760244182<br>N-1728-LN-RR-F12YL/8G/99H/C | - | Fiber indoor cable, All-Dielectric, LSZH Riser-Rated, Gel-Free, Loose Tube Rollable Ribbon, 1728 fiber, Singlemode G.657.A2, Feet jacket marking, Yellow jacket color |
| 860638318                                | - | MP012, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm   |