


# 760060343 | VP360-HCM-Kit-19

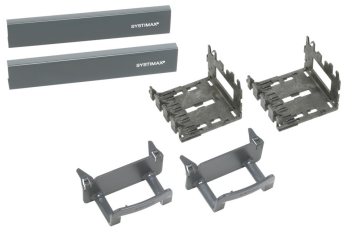

GigaSPEED X10D® VisiPatch® 360 Horizontal Cable Management Kit, 19 In.

## Product Classification

|                              |   |
|------------------------------|---|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   EMEA   Latin America   North America |
| <b>Portfolio</b>             | SYSTIMAX®   |
| <b>Product Type</b>          | Cable management hardware   |
| <b>Product Brand</b>         | VisiPatch®  |

## General Specifications

|                          |                |
|--------------------------|----------------|
| <b>Product Design</b>    | VisiPatch® 360 |
| <b>ANSI/TIA Category</b> | 6A             |

## Dimensions

|              |                     |
|--------------|---------------------|
| <b>Width</b> | 482.6 mm   19 in    |
| <b>Depth</b> | 299.72 mm   11.8 in |

## Environmental Specifications

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Operating Temperature</b> | -10 °C to +60 °C (+14 °F to +140 °F) |
| <b>Safety Standard</b>       | Austel   CE   UL   cUL               |

## Packaging and Weights

|                           |   |
|---------------------------|---|
| <b>Included</b>           | Two horizontal CM troughs   Two horizontal trough covers   Two pairs of back panel halves |
| <b>Packaging quantity</b> | 1   |

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |

# 760060343 | VP360-HCM-Kit-19

---

UK-ROHS

Compliant

