


FGS-MDSP-B

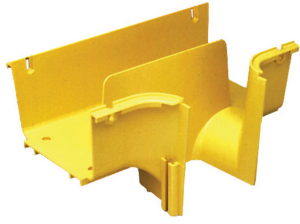

FiberGuide® Downspout with 4in Exit, 4x6in, Yellow

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Downspout |
| Product Brand | FiberGuide® |
| Product Series | FGS |

General Specifications

| | |
|---------------------|------------|
| Color | Yellow |
| Orientation | Horizontal |
| Section Type | Downspout |

Dimensions

| | |
|--------------------------|-------------------------------|
| Height | 160 mm 6.299 in |
| Width | 195 mm 7.677 in |
| Length | 329 mm 12.953 in |
| System Dimensions | 102 mm x 152 mm (4 in x 6 in) |

Ordering Tree

FGS-MDSP-B



Section Color

| | | |
|---|-------|--------|
| 9 | empty | yellow |
| | B | black |

Section Size

| | | |
|----|-----|--------------------------------------|
| 10 | 2B | 4 x 6 in, 4 x 4 in dual drop |
| | A | 4 x 4 in |
| | A/I | 4 x 4 in, insertable |
| | B | 4 x 6 in, 4 x 4 in drop |
| | B/I | 4 x 6 in, insertable |
| | C | 2 x 2 in, extended |
| | EX- | extended |
| | F | 4 x 12 in, 4 x 6 in drop |
| | F/I | 4 x 12 in, 4 x 6 in drop, insertable |
| | G | 2 x 6 in, 2 x 2 in drop |
| | IMP | 4 x 6 in, dual drop with divider |
| | M | 4 x 18 in |

Material Specifications

Material Type Engineering Thermoplastic

Environmental Specifications

Flammability Rating CSA S143 | UL 2024 | UL 94 V-0

Halogen Characteristics Blue Angel | TCO '99 | WEEE

Safety Standard CSA | UL

Packaging and Weights

Weight, net 0.618 kg | 1.362 lb

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|---|
| CHINA-ROHS | Below maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |



