


CL-1210-U

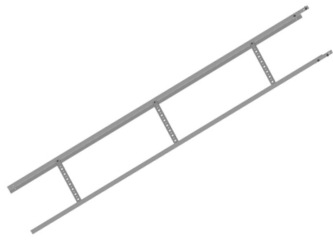

Universal Cable Ladder Kit, 38 in x 10 ft, 12-hole rung

Product Classification

Product Type Ladder kit

General Specifications

Cable Runs, quantity 12

Mounting Round and angle legs

Dimensions


Height 76.2 mm | 3 in

Width 965.2 mm | 38 in

Length 3048 mm | 120 in

CL-1210-U

Outline Drawing

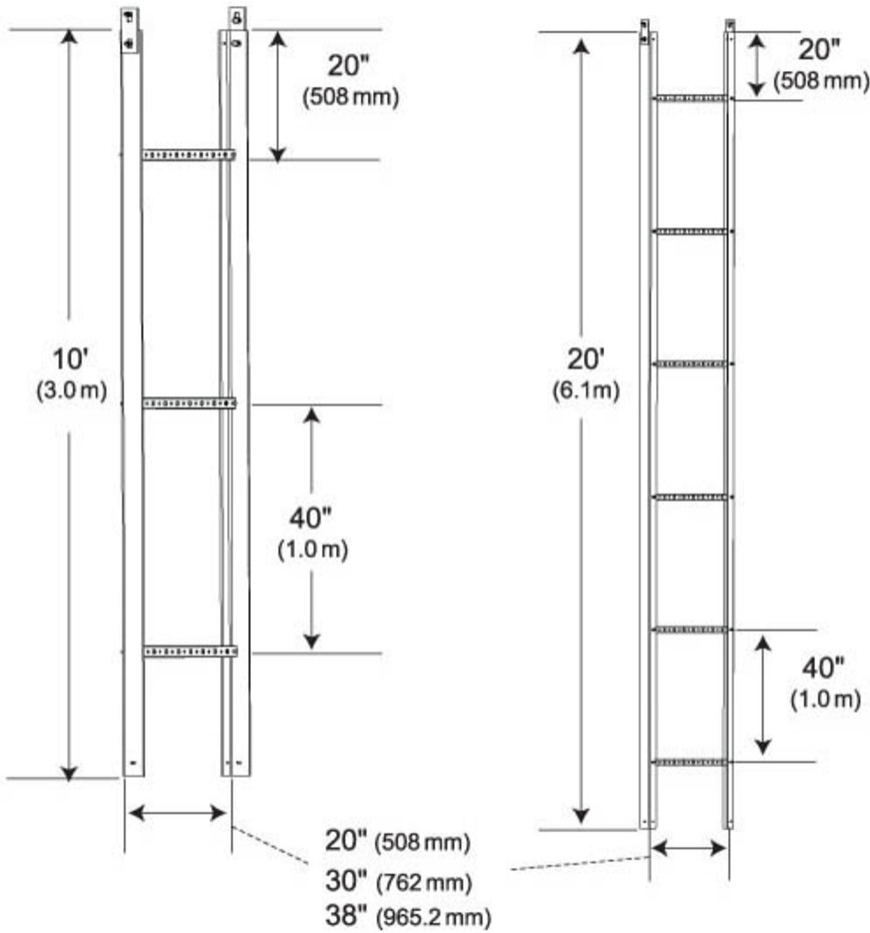

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Attachment kits | Ladder | Splice plates

Packaging quantity 1

Weight, net 28 kg | 61.729 lb

Regulatory Compliance/Certifications

Agency **Classification**

CL-1210-U

ISO 9001:2015


Designed, manufactured and/or distributed under this quality management system



Included Products

- HK-CL-U – Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members

HK-CL-U

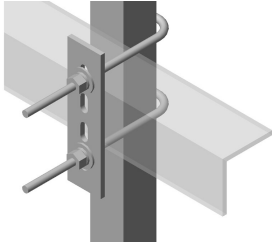

Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members

Product Classification

Product Type Ladder kit

General Specifications

Mounting Round and angle legs

Dimensions

Height 203.2 mm | 8 in

Width 127 mm | 5 in

Length 203.2 mm | 8 in

Mounting Diameter, maximum 114.3 mm | 4.5 in

Mounting Diameter, minimum 25.4 mm | 1 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included J-bolts | Plates

Packaging quantity 1

Weight, net 1.7 kg | 3.748 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

