


# RM-SS-S2

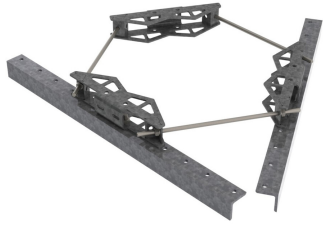

## Ring Mount Tie Back Support Kit

### Product Classification

**Product Type** Ring mount

### General Specifications

**Mounting** Monopole, 254–762 mm (10–30 in) OD

**Sectors, quantity** 1

### Dimensions

**Height** 254 mm | 10 in

**Width** 1,219.2 mm | 48 in

**Length** 1,219.2 mm | 48 in

**Mounting Diameter, maximum** 762 mm | 30 in

**Mounting Diameter, minimum** 254 mm | 10 in

**Mounting Circumference, maximum** 2,392.68 mm | 94.2 in

**Mounting Circumference, minimum** 797.56 mm | 31.4 in

### Material Specifications

**Material Type** Hot dip galvanized steel

### Packaging and Weights

**Included** Angle | Hardware | Mount

**Packaging quantity** 1

**Weight, net** 43.1 kg | 95.019 lb

### Regulatory Compliance/Certifications

#### Agency

CHINA-ROHS

REACH-SVHC

#### Classification

Below maximum concentration value

Compliant as per SVHC revision on [www.andrew.com/ProductCompliance](http://www.andrew.com/ProductCompliance)

# RM-SS-S2

---

ROHS Compliant

UK-ROHS Compliant

