


RM-SS-S2

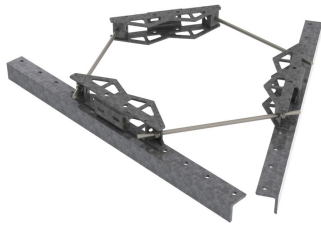

Ring Mount Tie Back Support Kit

Product Classification

Product Type Ring mount

General Specifications

Mounting Monopole, 254–762 mm (10–30 in) OD

Sectors, quantity 1

Dimensions

Height 254 mm | 10 in

Width 1,219.2 mm | 48 in

Length 1,219.2 mm | 48 in

Mounting Diameter, maximum 762 mm | 30 in

Mounting Diameter, minimum 254 mm | 10 in

Mounting Circumference, maximum 2,392.68 mm | 94.2 in

Mounting Circumference, minimum 797.56 mm | 31.4 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Angle | Hardware | Mount

Packaging quantity 1

Weight, net 43.1 kg | 95.019 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

RM-SS-S2

ROHS Compliant

UK-ROHS Compliant

