


# RR-HFBS5

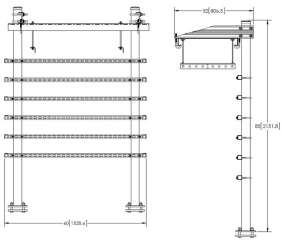

Remote Radio H-Frame, 5' Wide w/ Base Shoes

## Product Classification

**Product Type** Remote radio head unit mount


## Dimensions

**Height** 2159 mm | 85 in

**Width** 1524 mm | 60 in

**Length** 812.8 mm | 32 in

## Outline Drawing

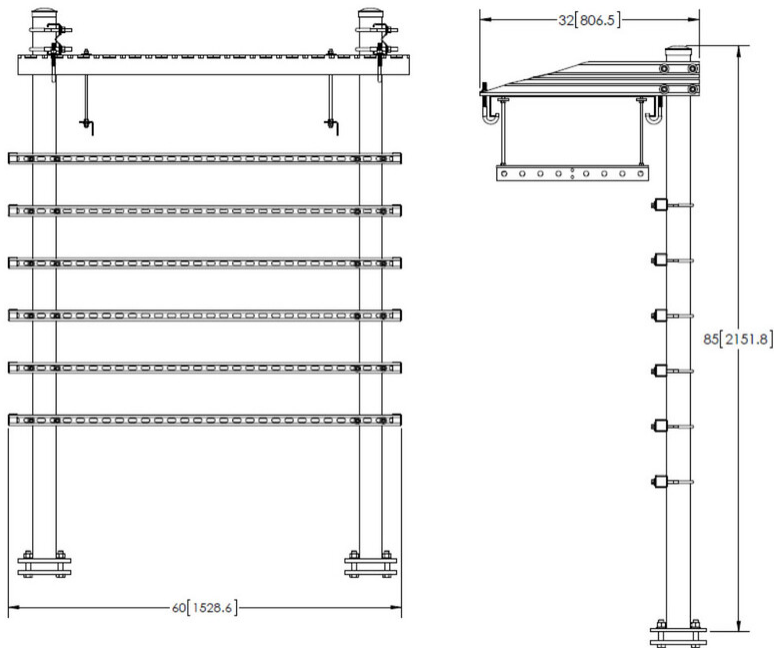

## Material Specifications

**Material Type** Hot dip galvanized steel

# RR-HFBS5

---

## Packaging and Weights

**Included** Hardware | Legs | Unistrut

**Packaging quantity** 1

**Weight, net** 334.4 kg | 737.225 lb

## Regulatory Compliance/Certifications

**Agency** **Classification**

ISO 9001:2015 Designed, manufactured and/or distributed under this quality management system

## Included Products

MF-130 – Direct Burial Pipe Column, 13 ft 4 in

# MF-130

---



Direct Burial Pipe Column, 13 ft 4 in

## Product Classification

**Product Type** Pipe column

## General Specifications

**Application** Direct burial

**Mounting** Waveguide bridge support bracket

**Pipe, quantity** 1

## Dimensions

**Height** 4064 mm | 160 in

**Width** 88.9 mm | 3.5 in


**Length** 88.9 mm | 3.5 in

**Pipe Length** 4,053.84 mm | 159.6 in

**Pipe Outer Diameter** 88.9 mm | 3.5 in

# MF-130

## Outline Drawing

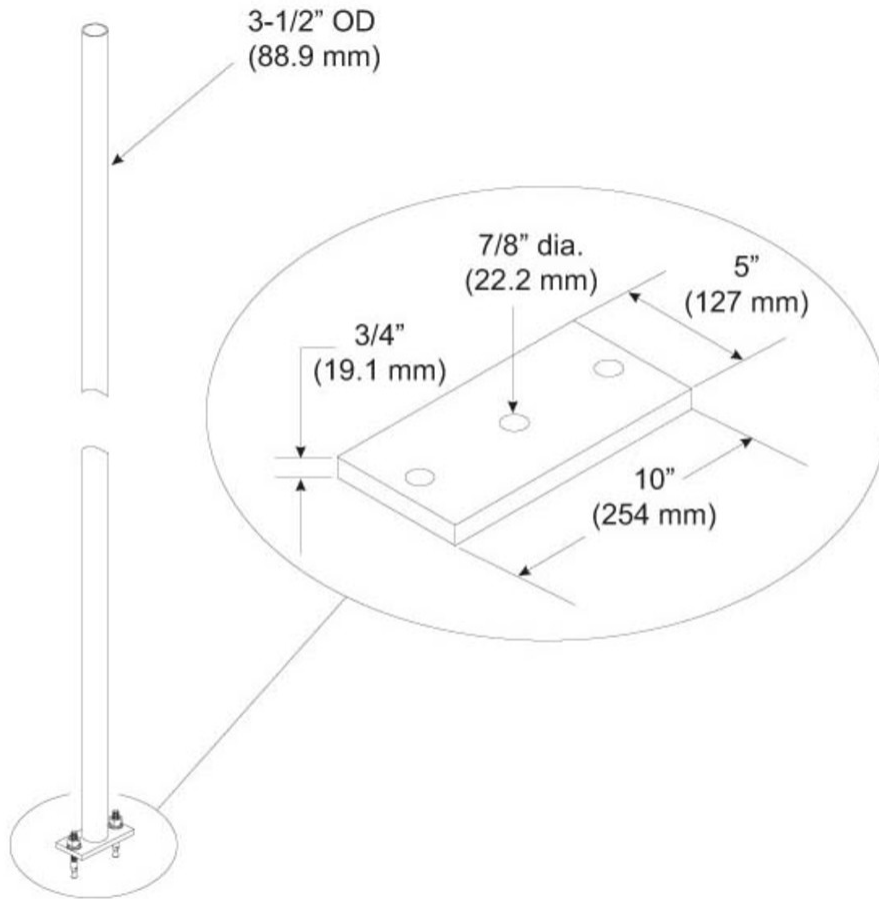

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Anchors | Pipe

**Packaging quantity** 1

**Weight, net** 45.8 kg | 100.972 lb

## Regulatory Compliance/Certifications

**Agency** **Classification**

# MF-130

---

CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

