

UHXMXMXAD

Base Product



Ultra Low Loss (ULL) Multimode OM4 MPO12 (Pinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 12-Fiber, Plenum

OBSOLETE

This product was discontinued on: April 30, 2024

Replaced By:

UHXMXMXCD Ultra Low Loss (ULL) OM4 MPO12 UPC (pinned) to MPO12 UPC (pinned) Fiber Trunk Cable Assembly, 12-Fiber, Armored Indoor Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Black
Color, connector A	Aqua
Connector B, quantity	1
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Armored Stranded
Furcation Color	Aqua


UHXMXMXAD

Interface, Connector A	MPO-12/UPC Male
Interface Feature, connector A	Pinned
Interface, Connector B	MPO-12/UPC Male
Interface Feature, connector B	Pinned
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

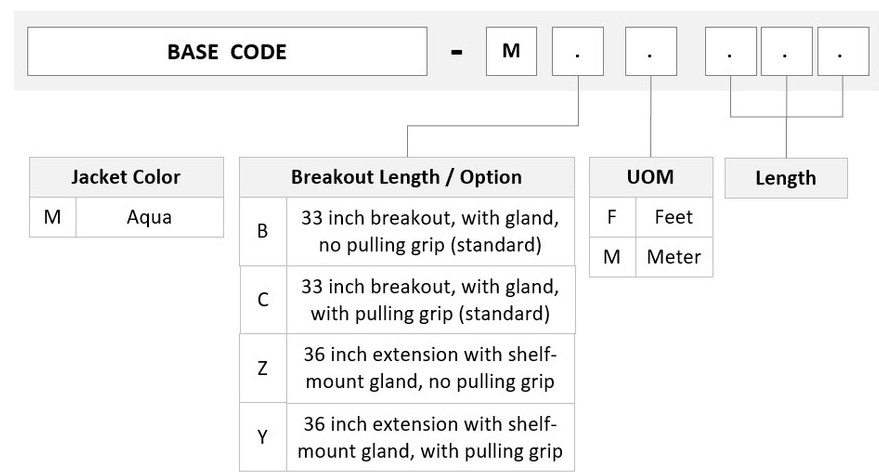

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
-----------------------------------	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

UHXMXMXAD

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760120022	–	Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, interlocking aluminum armored with plenum jacket, 12 fiber, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color
P-012-MZ-5K-F12AQ		
860366228	–	MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm