

SRC1-U3B2A1BE000



NOVUX™ Specialty Range Closure 50, splice/patch, 2x SC/APC adapter, 2x SC/APC Grade B 900µm pigtail, no splitters, 6 splices, SMOUV® 45mm splice protectors, black, no splitter, 2x NVX-CR-TI-SM-NN cable retention

- Modern drop solution offering providers the agility and flexibility to use it in last-mile fiber network applications, both above and below ground
- Protected from harsh conditions by CommScope's Octopus gel sealing technology
- Agnostic to connectivity technologies: splice, connector, field-installable connector for agility and flexibility
- Identification plate for either QR code or customer logo
- QR code and CommScope cTrak® app for one-click access to all product information

Product Classification

| | |
|-----------------------------------|---|
| Regional Availability | Asia EMEA Latin America |
| Regional Availability Note | Contact your local CommScope representative for specific availability |
| Product Type | Single-ended, rectangular fiber closure |
| Product Brand | NOVUX™ |
| Product Series | SRC50 |

General Specifications

| | |
|--|--|
| Cable Capacity, Drop | 2 Flat 8.0 x 4.5 mm (0.30 x 0.17 in) 2 Round 1.2–8.0 mm (0.05–0.31 in) |
| Cable Ports Quantity, total | 2 multi-out ports (4 cables) |
| Cable Sealing Type | Compressed gel |
| Cable Termination Attachments, quantity | 2 |
| Closure Sealing Type | Hinged with latch |
| Closure Style | Single-ended |
| Color | Black |
| Mounting | Handhole Pedestal Wall/Pole Mount, mounting kit included |
| Network Area Type | Drop |
| Port Type | SC/APC |
| Port, quantity | 2 |
| Splice Tray Included, quantity | 1 |
| Splice Tray Type Included | 6-way, heat shrink |


SRC1-U3B2A1BE000






| | |
|--|---------------|
| Splicing Capacity, maximum | 6 |
| Splicing Capacity, Single Fusion, maximum | 6 |
| Splicing Type, Supported | Single fusion |
| Splitter Type | No splitter |
| Splitter, quantity | 0 |

Dimensions
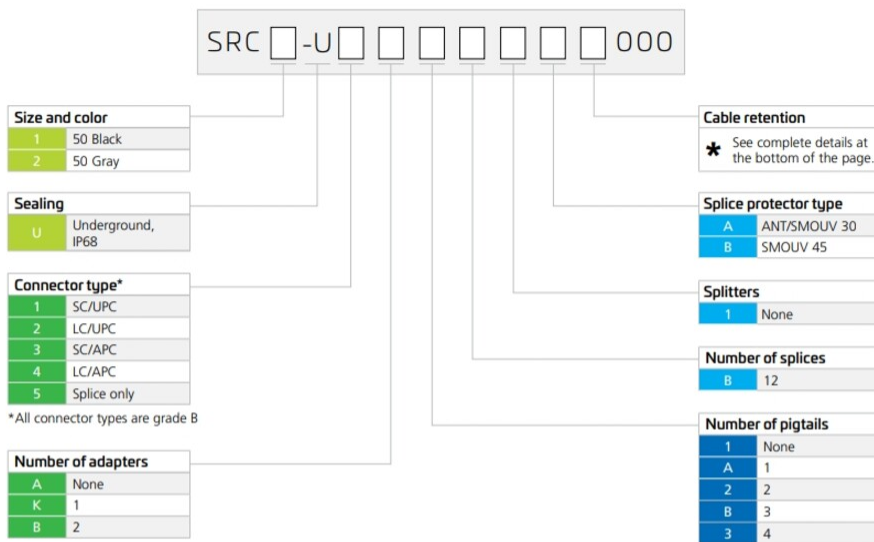
| | |
|---------------------------------------|--------------------|
| Height | 267 mm 10.512 in |
| Width | 87 mm 3.425 in |
| Depth | 49 mm 1.929 in |
| Cable Entry Drop Port Diameter | 8 mm (0.31 in) mm |

Ordering Tree



| | |
|---|---|
| Cable retention^a A None B NVX-CR-MC-FT-NN C NVX-CR-MC-RD-NN D NVX-CR-SA-SM-NN E NVX-CR-TI-SM-NN F NVX-CR-DU-FL-NN | Cable Termination Unit (CTU) options <div style="display: flex; justify-content: space-between;"> <div style="width: 45%;"> <p>B</p>  <p>NVX-CR-MC-FT-NN</p> <ul style="list-style-type: none"> Flat cable Metal clip Range 3 x 5 to 4 x 8 mm </div> <div style="width: 45%;"> <p>C</p>  <p>NVX-CR-MC-RD-NN</p> <ul style="list-style-type: none"> Round cable Metal clip Range 4 to 6.2 mm </div> <div style="width: 45%;"> <p>D</p>  <p>NVX-CR-SA-SM-NN</p> <ul style="list-style-type: none"> Round cable Dia up to 8 mm Strength member Aramid yarns Single layer </div> <div style="width: 45%;"> <p>E</p>  <p>NVX-CR-TI-SM-NN</p> <ul style="list-style-type: none"> Round cable Dia up to 8 mm Aramid yarns Single layer </div> <div style="width: 45%;"> <p>F</p>  <p>NVX-CR-DU-FL-NN</p> <ul style="list-style-type: none"> Round cable Dia up to 6.2 mm Aramid yarns Dual layer Compact length </div> </div> |
|---|---|

^a 2 cable attachments are supplied.

SRC1-U3B2A1BE000

Material Specifications

Material Type Impact-resistant polymer

Optical Specifications

Fiber Type G.657.A1 | G.657.A2 | G.657.B3

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Environmental Space Above ground | Below ground | Direct burial

Qualification Standards IEC 60529, IP68 + 2 m waterhead | IEC 61753-1, category G

UV Resistance UV stabilized

Water Resistance Flash test valve at 2 psi (20 kPa)

Packaging and Weights

Packaging quantity 1

Packaging Type Box | Carton

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system




Included Products

NVX-CR-TI-SM-NN

- NOVUX™ Cable Termination Unit (CTU) for round cables up to 8 mm diameter, with aramide years, single layer

NVX-CR-TI-SM-NN

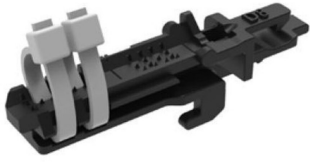

NOVUX™ Cable Termination Unit (CTU) for round cables up to 8 mm diameter, with aramide yarns, single layer

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia EMEA Latin America North America |
| Product Type | Cable termination kit |
| Product Brand | NOVUX™ |
| Product Series | CSC |

General Specifications

| | |
|--------------------|---------------------------------|
| Application | For use with CSC Fiber closures |
| Color | Black |

Packaging and Weights

| | |
|---------------------------|-----------|
| Packaging quantity | 20 |
| Packaging Type | Bag Box |

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|---|
| CHINA-ROHS | Below maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |

