


# FGWMPUCRP

---

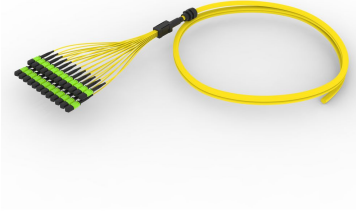

Singlemode MPO12 (Unpinned) to Unconnectorized, InstaPATCH® 360 Pre-terminated Fiber Trunk Cable Assembly, 288-Fiber, Plenum

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Product Brand</b>         | InstaPATCH® 360  |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |                   |
|-------------------------------------|-------------------|
| <b>Color, boot A</b>                | Black             |
| <b>Color, connector A</b>           | Green             |
| <b>Construction Type</b>            | Stranded          |
| <b>Fibers per Subunit, quantity</b> | 12                |
| <b>Furcation Color</b>              | Yellow            |
| <b>Interface, Connector A</b>       | MPO-12/APC Female |
| <b>Interface, Connector B</b>       | Unterminated      |
| <b>Jacket Color</b>                 | Yellow            |
| <b>Polarity</b>                     | Method B (LL)     |
| <b>Total Fibers, quantity</b>       | 288               |

## Dimensions

|   |          |
|---|----------|
| <b>Breakout Length</b>                  | 33 in    |
| <b>Cable Assembly Length Range (m)</b>  | 3 – 999  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

# FGWMPUCRP

## Ordering Tree

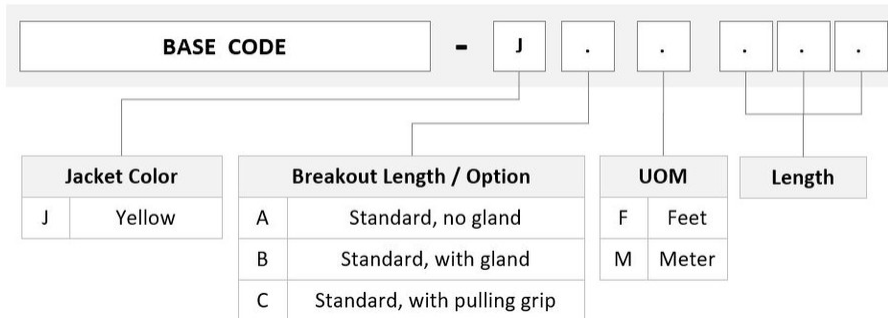

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Plenum

## Included Products

- 760239140 – Indoor Plenum All-Dielectric Central Tube Rollable Ribbon Cable
- P-288-CN-RR-F12YL/8G/99E
- 860638318 – MPO12, ULTRA LOW LOSS, FEMALE, SM, GREEN, 3mm