


# MC-PM12M-12C-96

---

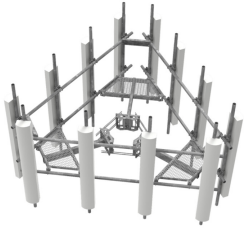

ATLAS 12 ft Monopole Platform with (12) 2.88" OD x 96" Antenna Pipes.  
Includes Top Rail Kit.

The innovative ATLAS Monopole Platform provides high-load performance, Lower EPA, and reduced weight – all with a single-point tower connection.

NOTE: Engineering loading based on Antenna pipes vertically centered on main horizontal face.

## Product Classification

<b>Product Type</b>	Monopole platform kit
<b>Product Series</b>	ATLAS
<b>Country Specific for</b>	United States

## General Specifications

<b>Mounting</b>	Monopole, 304.8–1270 mm (12–50 in) OD
<b>Pipe, quantity</b>	12
<b>Sectors, quantity</b>	3

## Dimensions

<b>Height</b>	2,438.4 mm   96 in
<b>Face Width</b>	45.72 m   150 ft
<b>Platform Width</b>	3,810 mm   150 in
<b>Width</b>	3,810 mm   150 in
<b>Pipe Length</b>	2,438.4 mm   96 in
<b>Face Support Pipe Diameter</b>	73.025 mm   2.875 in
<b>Pipe Outer Diameter</b>	73.025 mm   2.875 in
<b>Mounting Circumference, maximum</b>	1,143 mm   45 in
<b>Mounting Circumference, minimum</b>	304.8 mm   12 in

## Mechanical Specifications

<b>Wind Rating</b>	For Specifications, please contact <a href="mailto:steelproducts@commscope.com">steelproducts@commscope.com</a> or call 800-255-1479
--------------------	--

## Packaging and Weights

# MC-PM12M-12C-96

---

**Included** Mounting hardware | Plain end pipes (12) | Platform | Rail | Ring mount  
**Weight, net** 1,025.119 kg | 2260 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## \* Footnotes

**Wind Rating** BWS—Base Wind Speed; FBC—Florida Building Code