


# BLK-RIFC-A04B0

---

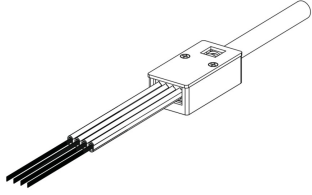

Fiber Optic Ribbon Breakout Kit, 12F/ribbon, 72F/tube, 5-8 mm central tube outside diameter, 4 tubes/leg

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Product Type</b>	Fiber breakout kit, rectangular
<b>Product Series</b>	BLK-R

## General Specifications

<b>Application</b>	For use with ribbon fiber cables
<b>Breakout Legs, quantity</b>	1
<b>Fibers per Ribbon, maximum</b>	12
<b>Fibers per Tube, maximum</b>	72
<b>Tube Type</b>	Ribbon IFC
<b>Tubes per Leg, quantity</b>	4

## Dimensions

<b>Tube Length</b>	5,001.26 mm   196.9 in
<b>Central Tube Outer Diameter</b>	5 mm – 8 mm (0.20 in – 0.33 in)

## Environmental Specifications

<b>Environmental Space</b>	Indoor
----------------------------	--------

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Bag   Carton

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# BLK-RIFC-A04B0

---

ROHS

Compliant

UK-ROHS

Compliant

