


UKGMPMXAL

Base Product

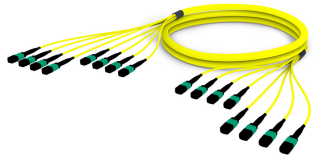

Ultra Low Loss (ULL) Singlemode MPO12 (Unpinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 96-Fiber, Low Smoke Zero Halogen (LSZH)

OBSOLETE

This product was discontinued on: April 30, 2024

Replaced By:

UKGMPMXCL

Ultra Low Loss (ULL) Singlemode MPO12 (Unpinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 96-Fiber, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability

Asia | Australia/New Zealand | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Product Brand

SYSTIMAX ULL

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration | Not available in the United States or Canada

General Specifications

Connector A, quantity	8
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	8
Color, boot B	Black
Color, connector B	Green
Construction Type	Armored Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface Feature, connector A	Unpinned
Interface, Connector B	MPO-12/APC Male

UKGMPMXAL

Interface Feature, connector B	Pinned
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	96

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760249591 N-096-MZ-8G1-F12YL	–	Fiber indoor cable, Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Singlemode G.657.A2, 96 fiber multi-unit with 12 fiber subunits, Feet jacket marking, Yellow jacket color
---------------------------------	---	---

UKGMPMXAL

- 860638317 – MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm
- 860638318 – MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm