

# SRC3-U5A1C1BD000



NOVUX™ Specialty Range Closure 100, splice only, no adapters, no splitters, 24 splices, SMOUV® 45mm splice protectors, black, 2x NVX-CR-SA-SM-NN cable retention

- Modern drop solution offering providers the agility and flexibility to use it in last-mile fiber network applications, both above and below ground
- Protected from harsh conditions by CommScope's Octopus gel sealing technology
- Agnostic to connectivity technologies: splice, connector, field-installable connector for agility and flexibility
- Identification plate for either QR code or customer logo
- QR code and CommScope cTrak® app for one-click access to all product information

## Product Classification

|                                   |   |
|-----------------------------------|---|
| <b>Regional Availability</b>      | Asia   EMEA   Latin America   North America                           |
| <b>Regional Availability Note</b> | Contact your local CommScope representative for specific availability |
| <b>Product Type</b>               | Single-ended, rectangular fiber closure                               |
| <b>Product Brand</b>              | NOVUX™  |
| <b>Product Series</b>             | SRC100  |

## General Specifications

|  |   |
|--|---|
| <b>Cable Capacity, Drop</b>                    | 4 Flat 8.0 x 4.5 mm (0.30 x 0.17 in)   4 Round 1.2–8.0 mm (0.05–0.31 in)        |
| <b>Cable Ports Quantity, total</b>             | 4 multi-out ports (8 cables)  |
| <b>Cable Sealing Type</b>                      | Compressed gel  |
| <b>Cable Termination Attachments, quantity</b> | 2   |
| <b>Closure Sealing Type</b>                    | Hinged with latch   |
| <b>Closure Style</b>                           | Single-ended  |
| <b>Color</b>                                   | Black   |
| <b>Mounting</b>                                | Handhole   Partially buried   Pedestal   Wall/Pole Mount, mounting kit included |
| <b>Network Area Type</b>                       | Drop  |
| <b>Port Type</b>                               | No adapter   No adapter   |
| <b>Port, quantity</b>                          | 0   |
| <b>Splice Tray Included, quantity</b>          | 1   |
| <b>Splice Tray Type Included</b>               | 24-way, heat shrink   |


# SRC3-U5A1C1BD000

|  |               |
|--|---------------|
| <b>Splicing Capacity, maximum</b>                | 24            |
| <b>Splicing Capacity, Single Fusion, maximum</b> | 24            |
| <b>Splicing Type, Supported</b>                  | Single fusion |
| <b>Splitter Type</b>                             | No splitter   |
| <b>Splitter, quantity</b>                        | 0             |

## Dimensions



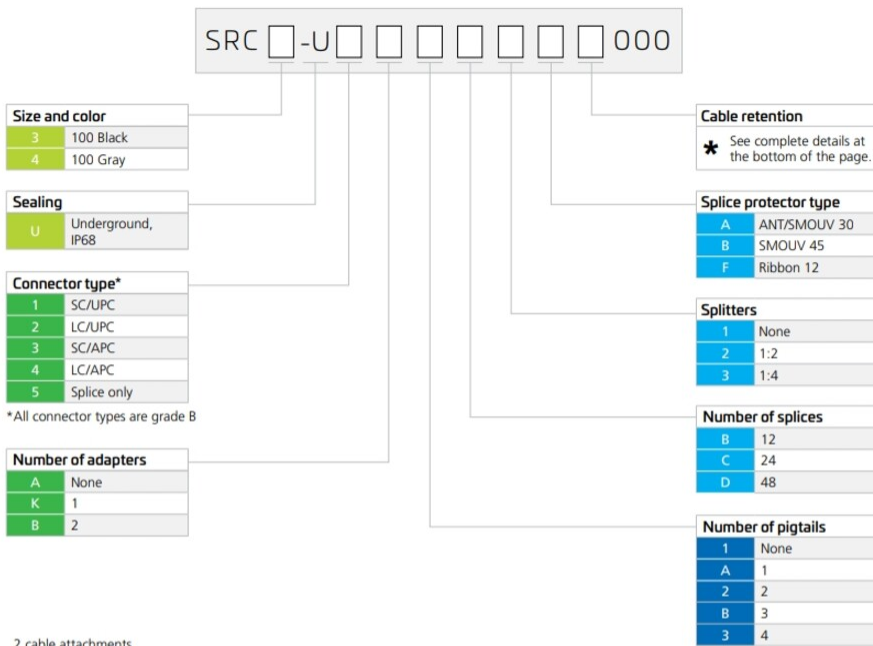


|                                       |                    |
|---------------------------------------|--------------------|
| <b>Height</b>                         | 267 mm   10.512 in |
| <b>Width</b>                          | 117 mm   4.606 in  |
| <b>Depth</b>                          | 49 mm   1.929 in   |
| <b>Cable Entry Drop Port Diameter</b> | 8 mm (0.31 in) mm  |

## Ordering Tree



\*All connector types are grade B

2 cable attachments are supplied.

| Cable retention*                           | Cable Termination Unit (CTU) options  |  |   |  |  |
|--|---|--|---|--|--|
| A: None                                    | <b>B</b>                       | <b>C</b>                  | <b>D</b>   | <b>E</b>                                        | <b>F</b>    |
| B: NVX-CR-MC-FT-NN                         | <b>NVX-CR-MC-FT-NN</b>  | <b>NVX-CR-MC-RD-NN</b>   | <b>NVX-CR-SA-SM-NN</b>  | <b>NVX-CR-TI-SM-NN</b>   | <b>NVX-CR-DU-FL-NN</b>   |
| C: NVX-CR-MC-RD-NN                         | <ul style="list-style-type: none"> <li>Flat cable</li> <li>Metal clip</li> <li>Range 3 x 5 to 4 x 8 mm</li> </ul> | <ul style="list-style-type: none"> <li>Round cable</li> <li>Metal clip</li> <li>Range 4 to 6.2 mm</li> </ul> | <ul style="list-style-type: none"> <li>Round cable</li> <li>Dia up to 8 mm</li> <li>Strength member</li> <li>Aramide yarns</li> <li>Single layer</li> </ul> | <ul style="list-style-type: none"> <li>Round cable</li> <li>Dia up to 8 mm</li> <li>Aramide yarns</li> <li>Single layer</li> </ul> | <ul style="list-style-type: none"> <li>Round cable</li> <li>Dia up to 6.2 mm</li> <li>Aramide yarns</li> <li>Dual layer</li> <li>Compact length</li> </ul> |
| D: NVX-CR-SA-SM-NN                         |   |  |   |  |  |
| E: NVX-CR-TI-SM-NN                         |   |  |   |  |  |
| F: NVX-CR-DU-FL-NN                         |   |  |   |  |  |
| G: 4xNVX-CR-MC-FT-NN                       |   |  |   |  |  |
| H: 4xNVX-CR-MC-RD-NN                       |   |  |   |  |  |
| I: 4xNVX-CR-SA-SM-NN                       |   |  |   |  |  |
| J: 4xNVX-CR-TI-SM-NN                       |   |  |   |  |  |
| K: 4xNVX-CR-DU-FL-NN                       |   |  |   |  |  |
| L: 2xNVX-CR-MC-FT-NN and 2xNVX-CR-MC-RD-NN |   |  |   |  |  |

# SRC3-U5A1C1BD000

---

## Material Specifications

**Material Type** Impact-resistant polymer

## Optical Specifications

**Fiber Type** G.657.A1 | G.657.A2 | G.657.B3

## Environmental Specifications

**Operating Temperature** -40 °C to +70 °C (-40 °F to +158 °F)

**Environmental Space** Above ground | Below ground | Direct burial

**Qualification Standards** IEC 60529, IP68 + 2 m waterhead | IEC 61753-1, category G

**UV Resistance** UV stabilized

**Water Resistance** Flash test valve at 2 psi (20 kPa)

## Packaging and Weights

**Packaging quantity** 10

**Packaging Type** Box | Carton

## Regulatory Compliance/Certifications

### Agency

ISO 9001:2015

### Classification

Designed, manufactured and/or distributed under this quality management system



## Included Products

NVX-CR-SA-SM-NN – NOVUX™ Cable Termination Unit (CTU) for round cables up to 8 mm diameter, with strength member, aramide yarns, single layer

# NVX-CR-SA-SM-NN

---



NOVUX™ Cable Termination Unit (CTU) for round cables up to 8 mm diameter, with strength member, aramide yarns, single layer

## Product Classification

|                              |   |
|------------------------------|---|
| <b>Regional Availability</b> | Asia   EMEA   Latin America   North America |
| <b>Product Type</b>          | Cable termination kit                       |
| <b>Product Brand</b>         | NOVUX™                                      |
| <b>Product Series</b>        | CSC   |

## General Specifications

|                    |                                 |
|--------------------|---------------------------------|
| <b>Application</b> | For use with CSC Fiber closures |
| <b>Color</b>       | Black                           |

## Packaging and Weights

|                           |           |
|---------------------------|-----------|
| <b>Packaging quantity</b> | 20        |
| <b>Packaging Type</b>     | Bag   Box |

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>   |
|---------------|---|
| CHINA-ROHS    | Below maximum concentration value   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant   |
| UK-ROHS       | Compliant   |

