


860658161

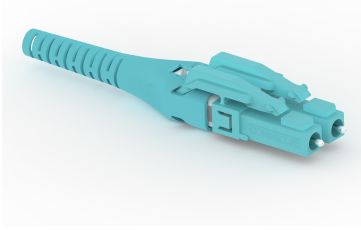

2.0 mm LC/UPC Uniboot GEN 1.5, Aqua

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Product Type	Fiber connector boot

General Specifications

Color	Aqua
Compatible Interface	LC
Ferrule Geometry	Flat

Dimensions

Compatible Cable Diameter	2 mm 0.079 in
----------------------------------	-----------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4
Attenuation, nominal	0.13 dB
Insertion Loss, maximum	0.15 dB
Return Loss, minimum	35 dB

Packaging and Weights

Packaging Type	Bag
-----------------------	-----

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

860658161

UK-ROHS

Compliant

