


# U3XQVQZTR

## Base Product

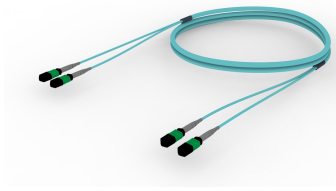

Ultra Low Loss (ULL) OM4 MPO8 APC (Non-Pinned) to MPO8 APC (Pinned), Fiber Trunk Cable Assembly, 16-Fiber, LSZH B2ca

## Product Classification

<b>Regional Availability</b>	Europe
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	2
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	2
<b>Color, boot B</b>	Gray
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-08/APC Female
<b>Interface, Connector B</b>	MPO-08/APC Male
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	16

## Dimensions


<b>Breakout Length</b>	22 in
<b>Cable Assembly Length Range (m)</b>	3 – 305

# U3XQVQZTR

Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree

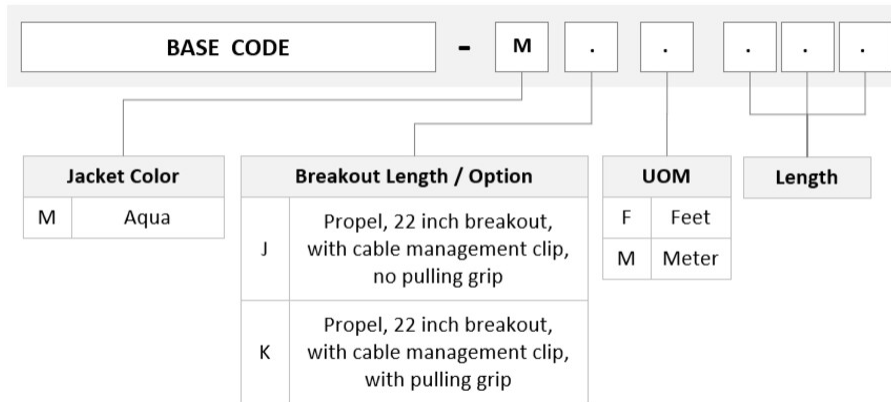

## Mechanical Specifications

**Cable Retention Strength, maximum**

11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode**

Multimode

**Fiber Type**

OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature**

-10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance**

B2ca

**Environmental Space**

Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

**Agency**

**Classification**

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant



## Included Products

- |                                       |   |   |
|---------------------------------------|---|---|
| 760253117<br>N-016-MP-5K-F08AQ/20T/B2 | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 16 fiber with 8 fiber 2.0mm subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color, B2ca flame rating |
| 860662230                             | - | MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm  |
| 860662232                             | - | MPO8,ULL,Multimode,FEMALE,APC,GREEN,2 mm  |