

Ultra Low Loss (ULL) Singlemode MPO8 (Pinned) to unconnectorized, Fiber Trunk Cable Assembly, 72-Fiber, Dual Rated (OFNR/LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	9
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	0
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-08/APC Male
Interface, Connector B	Unterminated
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	72


Dimensions

Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305

UJGQXUCTK

Cable Assembly Length Range (ft) 10 – 999

Ordering Tree

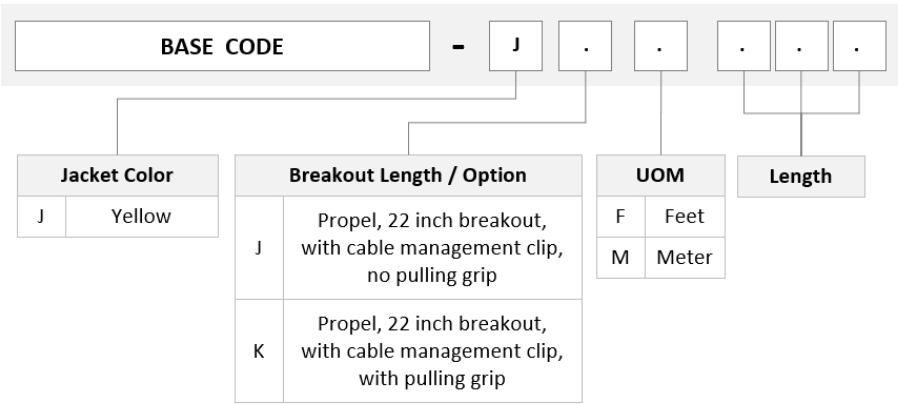

UJGQXUCTK

N-072-MP-8G1-F08YL/20T/D		2.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating
860659022	–	MPO-08, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm