


ARA-22

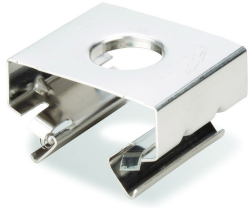

Anchor Rail Adapter, 22 mm

Product Classification

Product Type	Adapter
Product Brand	HELIAX®
Ordering Note	ANDREW® standard product (Global)

General Specifications

Adapter Type	Adapter
Mounting	3/4 in through hole

Dimensions

Outside Width	1,285.24 mm 50.6 in
Outside Length	1,178.56 mm 46.4 in
Material Thickness	2.591 mm 0.102 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Double stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	14 cm 5.512 in
Width, packed	14 cm 5.512 in
Length, packed	8 cm 3.15 in
Packaging quantity	10
Weight, gross	0.97 kg 2.138 lb

Regulatory Compliance/Certifications

ARA-22

Agency

Classification

ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.andrew.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant