


FGS-HNTS-F-5/8-A

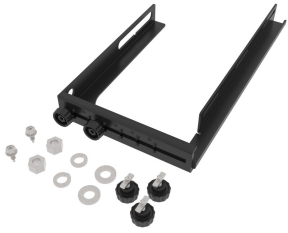

FiberGuide® Top Support Adjustable C-Bracket Kit, 5/8in for 4x12in System

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Support mounting kit
Product Brand	FiberGuide®
Product Series	FGS

General Specifications

Product Feature	Adjustable Height
Color	Black
Orientation	Horizontal
Section Type	Bracket
Bracket Type	C-bracket
Bracket Installation Type	N/A
Attachment Type	Threaded rod

Dimensions

Height	304.8 mm 12 in
Width	41.148 mm 1.62 in
Length	384.048 mm 15.12 in
Thread Size	5/8 in
System Dimensions	102 mm x 305 mm (4 in x 12 in)

Ordering Tree

FGS-HNTS-F-5/8-A

FGS - - - - - - -

For Section Size

9	<input type="text" value="empty"/>	4 x 4 in, 4 x 6 in
	<input type="text" value="F"/>	4 x 12 in

For Threaded Rod Size

10	<input type="text" value="1/2"/>	1/2 in
	<input type="text" value="1/2-LP"/>	1/2 in, low profile
	<input type="text" value="12MM"/>	12 mm
	<input type="text" value="12MM-LP"/>	12 mm, low profile
	<input type="text" value="14MM"/>	14 mm
	<input type="text" value="14MM-LP"/>	14 mm, low profile
	<input type="text" value="16MM"/>	16 mm
	<input type="text" value="16MM-LP"/>	16 mm, low profile
	<input type="text" value="5/8"/>	5/8 in
	<input type="text" value="5/8-LP"/>	5/8 in, low profile

11	<input type="text" value="A"/>	Adjustable
----	--------------------------------	------------

Material Specifications

Material Type Carbon steel

Packaging and Weights

Included Hardware

Packaging quantity 1

Weight, net 2.517 kg | 5.55 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS
REACH-SVHC
ROHS
UK-ROHS

Classification

Below maximum concentration value
Compliant as per SVHC revision on www.commscope.com/ProductCompliance
Compliant
Compliant

