


# SHK-3641-3-P

---

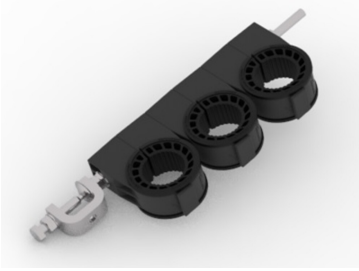

Single Hanger Kit for 36 to 41mm cable, triple stack; includes hardware and angle adapter

## Product Classification

<b>Product Type</b>	Hanger kit
<b>Product Brand</b>	ValuSite™
<b>Ordering Note</b>	CommScope® non-standard product

## General Specifications

<b>Cables per Hanger</b>	3
<b>Color</b>	Black
<b>Hanger Type</b>	Composite clamp
<b>Mounting</b>	M8 hardware

## Dimensions

<b>Maximum Stack Height</b>	3
<b>Height</b>	35.6 mm   1.402 in
<b>Width</b>	91.4 mm   3.598 in
<b>Length</b>	302.3 mm   11.902 in
<b>Compatible Cable Diameter Range</b>	36–41 mm
<b>Compatible Diameter, maximum</b>	40.9 mm   1.61 in
<b>Compatible Diameter, minimum</b>	36.1 mm   1.421 in

## Electrical Specifications

<b>Return Loss Effect, maximum</b>	0.1 dB
<b>DTF Effect, maximum</b>	0.1 dB

## Material Specifications

<b>Material Type</b>	Engineered plastic
----------------------	--------------------

## Mechanical Specifications

# SHK-3641-3-P

---

## Vibration Survival

≥4 hours at resonant frequency

## Environmental Specifications

### Operating Temperature

-40 °C to +85 °C (-40 °F to +185 °F)

### Corrosion Resistance, minimum with no degradation

≥500 hours in salt spray chamber

### Environmental Strength Capability

Double cable weight

### UV Resistance, minimum with no degradation

≥1000 hours exposure in accelerated UV life chamber

## Packaging and Weights

### Height, packed

20 cm | 7.874 in

### Width, packed

20 cm | 7.874 in

### Length, packed

35 cm | 13.78 in

### Included

Angle adapter | Hardware

### Packaging quantity

10

### Weight, gross

4.55 kg | 10.031 lb

## \* Footnotes

**Maximum Stack Height** Fiber, Hybrid, Power