


MC-HP14S-12-126

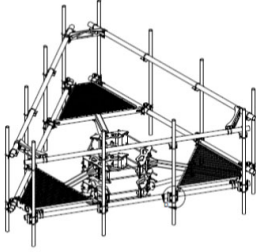

3-Sector Monopole Co-location Platform Kit, 10 in to 30 in OD, 14 ft 6 in face, includes twelve 126 in pipes

OBSOLETE

This product was discontinued on: March 9, 2022

Replaced By:

MC-HP14M-12-126 3-Sector Monopole Co-location Platform Kit, 12 in to 50 in OD, 14 ft 6 in face, includes twelve 126 in pipes

Product Classification

Product Type Monopole platform kit

General Specifications

Mounting Monopole, 254–762 mm (10–30 in) OD

Pipe, quantity 12

Sectors, quantity 3

Dimensions

Height 3,200.4 mm | 126 in

Face Width 4.42 m | 14.5 ft

Width 4,419.6 mm | 174 in

Pipe Length 3,200.4 mm | 126 in

Mounting Diameter, maximum 762 mm | 30 in

Mounting Diameter, minimum 254 mm | 10 in

Pipe Outer Diameter 60.96 mm | 2.4 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

MC-HP14S-12-126

| | |
|--------------------------------|--|
| Wind Rating | 120 mph (BWS) at 100 ft AGL 140 mph (3-second gust) at 150 ft AGL using Exposure D per FBC |
| Wind Rating Test Method | TIA/EIA-222 |

Packaging and Weights

| | |
|---------------------------|---|
| Included | Plain end pipes (12) Platform Rail Ring mount |
| Packaging quantity | 1 |
| Weight, net | 978.852 kg 2158 lb |

* Footnotes

| | |
|--------------------|--|
| Wind Rating | BWS—Base Wind Speed; FBC—Florida Building Code |
|--------------------|--|