


# VZWSMART-MSK12 | UNIVERSAL CROSSOVER PLATE

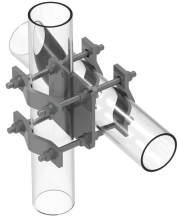

## UNIVERSAL CROSSOVER PLATE

Universal Crossover Plate, connects up to 4-1/2" OD x 4-1/2" OD Pipe (Pipe not included)

### Product Classification

<b>Product Type</b>	Clamp plate
<b>Ordering Note</b>	CommScope® non-standard product

### General Specifications

<b>Mounting</b>	Crossover plate
-----------------	-----------------

### Dimensions

<b>Mounting Diameter 2, maximum</b>	114.3 mm   4.5 in
<b>Mounting Diameter 2, minimum</b>	42.164 mm   1.66 in
<b>Mounting Diameter, maximum</b>	114.3 mm   4.5 in
<b>Mounting Diameter, minimum</b>	42.164 mm   1.66 in

### Material Specifications

<b>Material Type</b>	Hot dip galvanized steel
----------------------	--------------------------

### Packaging and Weights

<b>Included</b>	Clamps   Hardware   Plates
<b>Packaging quantity</b>	1
<b>Weight, net</b>	10 kg   22.046 lb

### Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



# VZWSMART-MSK12 | UNIVERSAL CROSSOVER PLATE

---