


VZWSMART-MSK13 | UNIVERSAL CHANNEL CROSSOVER

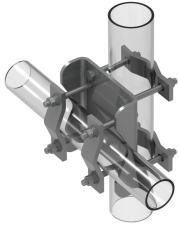

UNIVERSAL CHANNEL CROSSOVER

Universal Channel Crossover Plate, connects up to 4-1/2" OD to 3-1/2" OD Pipe (Pipe not included)

Product Classification

Product Type	Clamp plate
Ordering Note	ANDREW® non-standard product

General Specifications

Mounting	Crossover plate
-----------------	-----------------

Dimensions

Mounting Diameter 2, maximum	88.9 mm 3.5 in
Mounting Diameter 2, minimum	42.164 mm 1.66 in
Mounting Diameter, maximum	114.3 mm 4.5 in
Mounting Diameter, minimum	42.164 mm 1.66 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Packaging and Weights

Included	Clamps Hardware Plates
Packaging quantity	1
Weight, net	11.7 kg 25.794 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



VZWSMART-MSK13 | UNIVERSAL CHANNEL CROSSOVER
