


# UNXQPLUTK

## Base Product

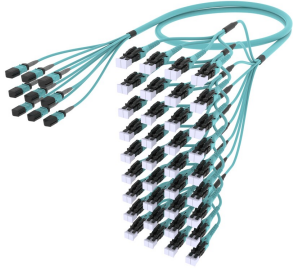

Ultra Low Loss ULL OM4 MPO8 UPC non-pinned to LC/UPC Uniboot Ruggedized fanout Cable, 72-Fiber, Dual Rated (OFNR/LSZH), 8 fiber PmP 2.0 mm

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Ruggedized fanout

### Product Brand

Propel | SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	9
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Aqua
<b>Connector B, quantity</b>	72
<b>Color, boot B</b>	Aqua
<b>Color, connector B</b>	Black
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-08/UPC Female
<b>Interface, Connector B</b>	LC/UPC
<b>Interface Feature, connector B</b>	Uniboot
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	72



# UNXQPLUTK

---

UK-ROHS

Compliant/Exempted



## Included Products

- |                                      |   |   |
|--------------------------------------|---|---|
| 760248168<br>N-072-MP-5K-F08AQ/20T/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 72 fiber multi-unit with 8 fiber 2.0mm subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color, Dca flame rating |
| 860658161                            | - | 2.0 mm LC/UPC Uniboot GEN 1.5, Aqua   |
| 860659019                            | - | MPO8, LL, MALE, OM3/4, AQUA, 2MM  |