


MT-F1587

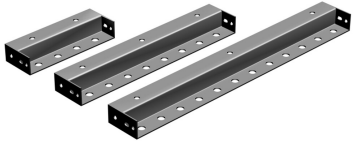

Wall-Mount Bracket for eight coaxial cable runs

Product Classification

Product Type Mounting bracket

General Specifications

Cable Runs, quantity 8

Hole, quantity 8

Mounting Walls

Dimensions

Height 101.6 mm | 4 in


Width 50.8 mm | 2 in

Length 558.8 mm | 22 in

Hole Size 3/4 in

MT-F1587

Outline Drawing

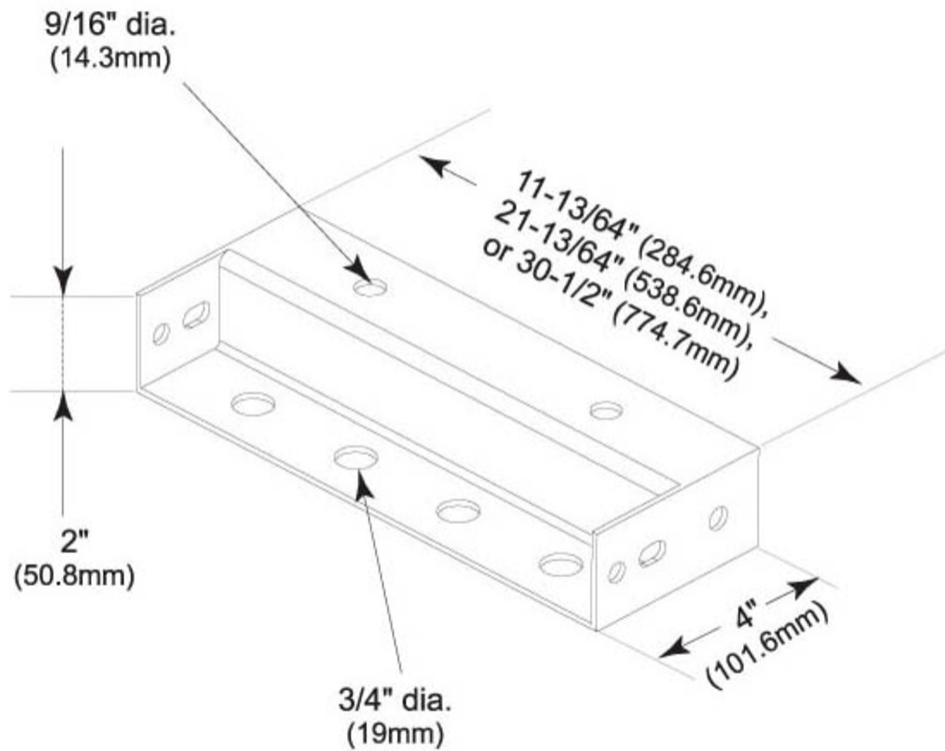

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating For Specifications, please contact steelproducts@commscope.com or call 800-255-1479

Packaging and Weights

Included Brackets

Packaging quantity 1

Weight, net 1.9 kg | 4.189 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value

MT-F1587

ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code