


# UKVMXMXCP

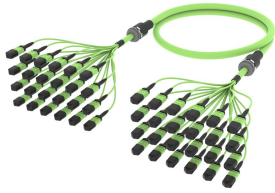

Ultra Low Loss (ULL) OM5 MPO12 UPC (pinned) to MPO12 UPC (pinned) Fiber Trunk Cable Assembly, 288-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	24
<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Lime green
<b>Connector B, quantity</b>	24
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Lime green
<b>Construction Type</b>	Armored   Stranded
<b>Furcation Color</b>	Lime green
<b>Interface, Connector A</b>	MPO-12/UPC Male
<b>Interface, Connector B</b>	MPO-12/UPC Male
<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	288

## Dimensions


<b>Breakout Length</b>	22 in
<b>Cable Assembly Length Range (m)</b>	3 – 305

# UKVMXMXCP

Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree

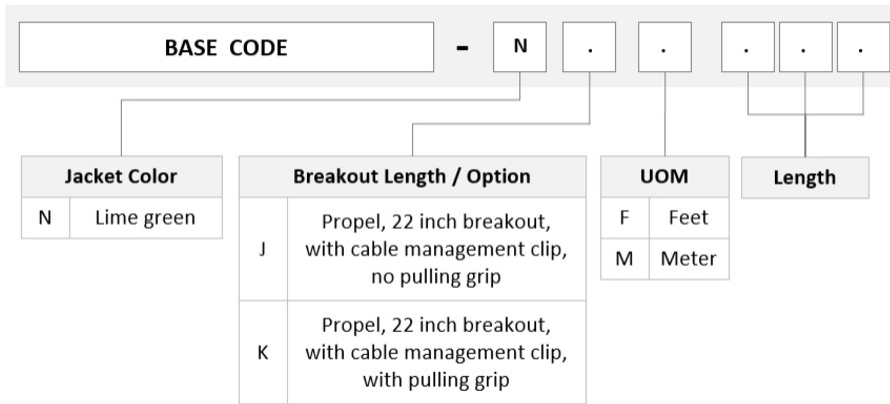

## Mechanical Specifications

**Cable Retention Strength, maximum**

11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode**

Multimode

**Fiber Type**

OM5, LazrSPEED®

## Environmental Specifications

**Operating Temperature**

-10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance**

Dca

**Environmental Space**

Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

**Agency**

**Classification**

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

# UKVMXMXCP

---



## Included Products

- 760249687  
N-288-MZ-5G-F12AQ/20T/B2 – Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM5, 288 fiber multi-unit with 12 fiber subunits, Feet jacket marking, Lime-green jacket color, B2ca flame rating
- 860659008 – MPO12, ULL, MALE, OM5, LIME, 2MM