


UKXRZRZ8Q

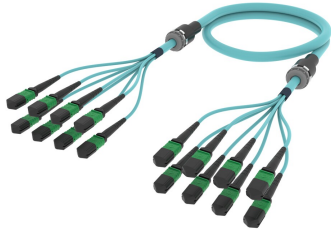

Ultra Low Loss (ULL) OM4 MPO16 APC (pinned) to MPO16 APC (pinned), Fiber Trunk Cable Assembly, 128-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Product Brand

Propel | SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	8
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	8
Color, boot B	Black
Color, connector B	Green
Construction Type	Armored Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-16/APC Male
Interface, Connector B	MPO-16/APC Male
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	16
Total Fibers, quantity	128


Dimensions

Breakout Length	22 in
------------------------	-------

UKXRZRZ8Q

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

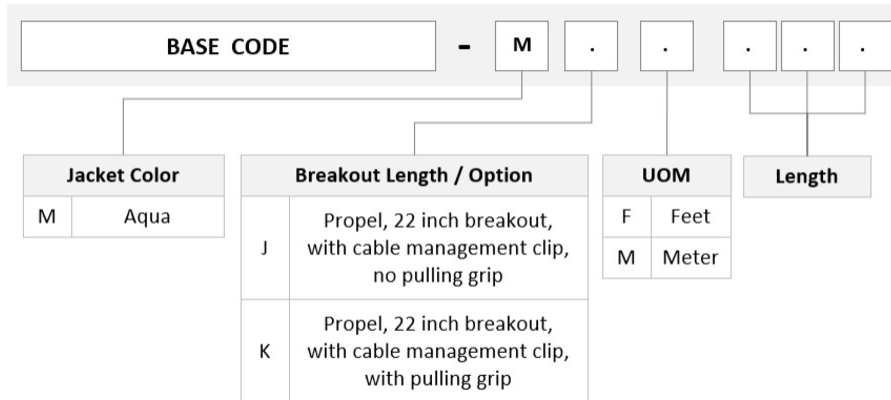

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0° 4.40 lb @ 90°
--	-------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	Dca
Environmental Space	Dual Rated LSZH/Riser Indoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

UKXRZRZ8Q



Included Products

- 760256198
N-128-MZ-5K-F16AQ/30T/B2
 - 860659158
- Fiber indoor cable, Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, OM4 multimode, 128 fiber, Feet jacket marking, Aqua jacket color, B2ca flame rating
 - Fiber Optic Connector Kit, multimode, OM3/OM4, MPO-16/APC, ULL, pinned, green, for 3 mm cable