

SA-B12

Stiff Arm / Tieback Bracket, includes 150" pipe



Product Classification

Product Type Stiff arm mount

General Specifications

Mounting Round and angle legs

Pipe, quantity 1

Dimensions

Height 203.2 mm | 8 in

Width 203.2 mm | 8 in

Length 3810 mm | 150 in

Pipe Length 3810 mm | 150 in

Mounting Diameter, maximum 88.9 mm | 3.5 in

Mounting Diameter, minimum 48.26 mm | 1.9 in

Pipe Outer Diameter 60.96 mm | 2.4 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Attachment hardware | Pipe

Packaging quantity 1

Weight, net 24.812 kg | 54.7 lb

Regulatory Compliance/Certifications

SA-B12

Agency

CHINA-ROHS

ISO 9001:2015

ROHS

UK-ROHS



Classification

Above maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant/Exempted

Compliant/Exempted

Included Products


MT-537

– Plain End Pipe, 2-3/8 in OD x 126 in .120" A500C 46Ksi

SA-B

– Stiff Arm /Tieback Brackets for 2-3/8 in OD pipe - Pipe not included

MT-537

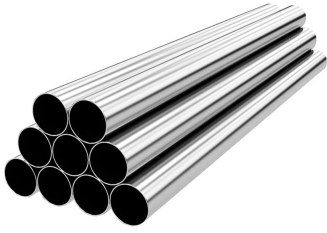

Plain End Pipe, 2-3/8 in OD x 126 in .120" A500C 46Ksi

A500 46 ksi steel

Product Classification

Product Type Plain end pipe

General Specifications

Pipe, quantity 1

Dimensions

Height 60.96 mm | 2.4 in

Width 60.96 mm | 2.4 in

Length 3,200.4 mm | 126 in

Pipe Length 3,200.4 mm | 126 in

Pipe Outer Diameter 60.96 mm | 2.4 in

Material Thickness 3.048 mm | 0.12 in

Material Specifications

Material Type A500 | Hot dip galvanized steel

Material Grade C

Material Strength 46 KSI

Packaging and Weights

Included Pipe

Packaging quantity 1

Weight, net 18 kg | 39.683 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

MT-537

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant





Stiff Arm /Tieback Brackets for 2-3/8 in OD pipe - Pipe not included

Product Classification

Product Type Stiff arm mount

General Specifications

Mounting Round and angle legs

Pipe, quantity 0

Dimensions

Height 152.4 mm | 6 in

Width 203.2 mm | 8 in

Length 203.2 mm | 8 in

Mounting Diameter, maximum 88.9 mm | 3.5 in

Mounting Diameter, minimum 48.26 mm | 1.9 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Attachment hardware | Brackets

Packaging quantity 1

Weight, net 8.301 kg | 18.3 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

SA-B

ROHS

Compliant

UK-ROHS

Compliant

