


SF-HPM-B

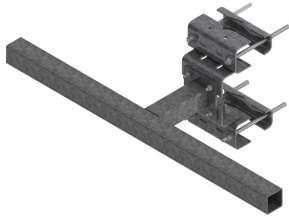

Heavy Duty Square T-Arm Base Kit, 2-7/8" OD pipe ordered separately

Product Classification

Product Type Co-location dual pipe mount kit

General Specifications

Mounting Angle 60°, 203.2 mm (8 in) | Angle 90°, 152.4 mm (6 in) | Straight or tapered legs up to 203.2 mm (8 in) OD

Pipe, quantity 0

Tower Taper Non-tapered | Tapered

Dimensions

Height 355.6 mm | 14 in

Face Width 1.676 m | 5.5 ft

Width 1,676.4 mm | 66 in

Mounting Diameter, maximum 203.2 mm | 8 in

Mounting Diameter, minimum 38.1 mm | 1.5 in

Stand-off Distance 508 mm | 20 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating 120 mph (BWS) at 100 ft AGL

Wind Rating Test Method TIA/EIA-222

Packaging and Weights

Included Clamps | Frame | Pipe mounts | Saddle mounts

Packaging quantity 1

Weight, net 63.412 kg | 139.8 lb

SF-HPM-B

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code