


SF-QV14-B

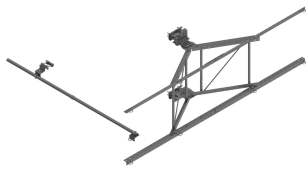

Quik-V Sector Frame, 14 ft face, pipe ordered separately

OBSOLETE

This product was discontinued on: July 29, 2022

Replaced By:

SFG21HD-12-4-96

G21HD High Capacity Sector Frame, 12.5 ft 2.88 in OD face pipes, includes four 96 in 2.375 OD antenna pipes

Product Classification

Product Type Tower sector frame

General Specifications

Mounting Angle 60°, 203.2 mm (8 in) | Angle 90°, 152.4 mm (6 in) | Straight or tapered legs up to 203.2 mm (8 in) OD

Pipe, quantity 0

Tower Taper Non-tapered | Tapered

Dimensions

Height 1,041.4 mm | 41 in

Face Width 4.42 m | 14.5 ft

Width 4,419.6 mm | 174 in

Length 863.6 mm | 34 in

Face Support Pipe Diameter 0 mm | 0 in

Mounting Diameter, maximum 203.2 mm | 8 in

Mounting Diameter, minimum 0 mm | 0 in

Pipe Outer Diameter 0 mm | 0 in

Stand-off Distance 863.6 mm | 34 in

Material Specifications

SF-QV14-B

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating 120 mph (BWS) at 100 ft AGL

Wind Rating Test Method TIA/EIA-222

Packaging and Weights

Included Clamps | Frame | Saddle mounts | Stiff arm

Packaging quantity 1

Weight, net 197.403 kg | 435.2 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code