


STS3-34

Three-way Snap-in Stand-off Adapter Kit for 3–4 in round members

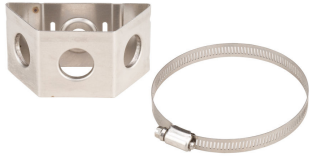

Product Classification

Product Type	Adapter
Product Brand	HELIAX®
Ordering Note	ANDREW® standard product in the United States and Canada

General Specifications

Adapter Type	Stand-off adapter
Mounting	3/4 in through hole Round member

Dimensions

Outside Width	1,012.444 mm 39.86 in
Outside Length	1,975.104 mm 77.76 in
Compatible Diameter, maximum	101.6 mm 4 in
Compatible Diameter, minimum	76.2 mm 3 in
Material Thickness	2.591 mm 0.102 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Double stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	12 cm 4.724 in
Width, packed	11 cm 4.331 in

STS3-34

Length, packed	1 cm 0.394 in
Packaging quantity	10
Weight, gross	0.58 kg 1.279 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.andrew.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

31670-3	- Round Member Adapter for 3-4 in round members
SA-38	- Three-Way Snap-in Stand-off Adapter has two slots for round member attachment and 3/8" holes for angle adapter integration. It includes three 3/4" holes for Snap-in hangers