


# STS3-45

---

## Three-way Snap-in Stand-off Adapter Kit for 4–5 in round members

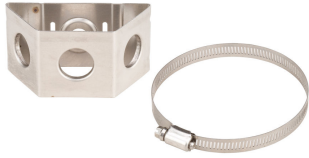

### Product Classification

|                      |                              |
|----------------------|------------------------------|
| <b>Product Type</b>  | Adapter                      |
| <b>Product Brand</b> | HELIAX®                      |
| <b>Ordering Note</b> | ANDREW® non-standard product |

### General Specifications

|                     |                     |
|---------------------|---------------------|
| <b>Adapter Type</b> | Stand-off adapter   |
| <b>Mounting</b>     | 3/4 in through hole |

### Dimensions

|                                     |                         |
|-------------------------------------|-------------------------|
| <b>Outside Width</b>                | 1,012.444 mm   39.86 in |
| <b>Outside Length</b>               | 1,975.104 mm   77.76 in |
| <b>Compatible Diameter, maximum</b> | 127 mm   5 in           |
| <b>Compatible Diameter, minimum</b> | 101.6 mm   4 in         |
| <b>Material Thickness</b>           | 2.591 mm   0.102 in     |

### Material Specifications

|                      |                 |
|----------------------|-----------------|
| <b>Material Type</b> | Stainless steel |
|----------------------|-----------------|

### Mechanical Specifications

|                        |                              |
|------------------------|------------------------------|
| <b>Maximum Loading</b> | Double stack, 1-5/8 in cable |
|------------------------|------------------------------|

### Packaging and Weights

|                       |                  |
|-----------------------|------------------|
| <b>Height, packed</b> | 12 cm   4.724 in |
| <b>Width, packed</b>  | 11 cm   4.331 in |

# STS3-45

---

|                           |                    |
|---------------------------|--------------------|
| <b>Length, packed</b>     | 1 cm   0.394 in    |
| <b>Packaging quantity</b> | 10                 |
| <b>Weight, gross</b>      | 0.58 kg   1.279 lb |

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.andrew.com/ProductCompliance">www.andrew.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |



## Included Products

|         |  |
|---------|--|
| 31670-4 | - Round Member Adapter for 4–5 in round members  |
| SA-38   | - Three-Way Snap-in Stand-off Adapter has two slots for round member attachment and 3/8" holes for angle adapter integration. It includes three 3/4" holes for Snap-in hangers |

# 31670-4

---



## Round Member Adapter for 4–5 in round members

### Product Classification

|                      |                                   |
|----------------------|-----------------------------------|
| <b>Product Type</b>  | Adapter                           |
| <b>Ordering Note</b> | ANDREW® standard product (Global) |

### General Specifications

|                     |                      |
|---------------------|----------------------|
| <b>Adapter Type</b> | Round member adapter |
|---------------------|----------------------|

### Dimensions

|                                     |                     |
|-------------------------------------|---------------------|
| <b>Compatible Diameter, maximum</b> | 127 mm   5 in       |
| <b>Compatible Diameter, minimum</b> | 101.6 mm   4 in     |
| <b>Material Thickness</b>           | 0.711 mm   0.028 in |

### Material Specifications

|                      |                 |
|----------------------|-----------------|
| <b>Material Type</b> | Stainless steel |
|----------------------|-----------------|

### Mechanical Specifications

|                                     |                              |
|-------------------------------------|------------------------------|
| <b>Installation Torque, maximum</b> | 6.6 ft lb   8.948 N-m        |
| <b>Installation Torque, minimum</b> | 4.1 ft lb   5.559 N-m        |
| <b>Maximum Loading</b>              | Triple stack, 1-5/8 in cable |

### Packaging and Weights

|                           |                    |
|---------------------------|--------------------|
| <b>Height, packed</b>     | 36 cm   14.173 in  |
| <b>Width, packed</b>      | 27 cm   10.63 in   |
| <b>Length, packed</b>     | 8 cm   3.15 in     |
| <b>Packaging quantity</b> | 10                 |
| <b>Weight, gross</b>      | 0.51 kg   1.124 lb |

### Regulatory Compliance/Certifications


# 31670-4

---

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.andrew.com/ProductCompliance">www.andrew.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |

# SA-38

---

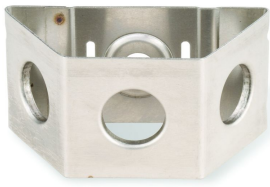

Three-Way Snap-in Stand-off Adapter has two slots for round member attachment and 3/8" holes for angle adapter integration. It includes three 3/4" holes for Snap-in hangers

## Product Classification

|                      |                                   |
|----------------------|-----------------------------------|
| <b>Product Type</b>  | Adapter                           |
| <b>Product Brand</b> | HELIAX®                           |
| <b>Ordering Note</b> | ANDREW® standard product (Global) |

## General Specifications

|                     |  |
|---------------------|--|
| <b>Adapter Type</b> | Stand-off adapter  |
| <b>Mounting</b>     | 3/4 in through hole   3/8 in through hole   Round member |

## Dimensions

|                           |                     |
|---------------------------|---------------------|
| <b>Height</b>             | 2.54 mm   0.1 in    |
| <b>Outside Width</b>      | 41.402 mm   1.63 in |
| <b>Outside Length</b>     | 85.852 mm   3.38 in |
| <b>Material Thickness</b> | 2.591 mm   0.102 in |

## Material Specifications

|                      |                 |
|----------------------|-----------------|
| <b>Material Type</b> | Stainless steel |
|----------------------|-----------------|

## Mechanical Specifications

|                        |                              |
|------------------------|------------------------------|
| <b>Maximum Loading</b> | Double stack, 1-5/8 in cable |
|------------------------|------------------------------|

## Packaging and Weights

|                           |                  |
|---------------------------|------------------|
| <b>Height, packed</b>     | 12 cm   4.724 in |
| <b>Width, packed</b>      | 11 cm   4.331 in |
| <b>Length, packed</b>     | 1 cm   0.394 in  |
| <b>Packaging quantity</b> | 10               |

# SA-38

---

**Weight, gross**                    0.58 kg | 1.279 lb

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.andrew.com/ProductCompliance">www.andrew.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |

