


FD3-AC144JDRGGBP2P

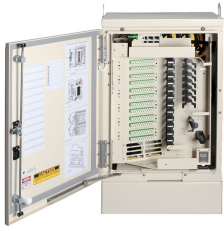

FDH 3000 Fiber Distribution Extra Small Cabinet, 144F, SC/APC, no splitters, flatdrop, 12 fiber flatdrop with HMFOC, 100 ft, 24FF

Product Classification

| | |
|------------------------------|------------------------|
| Regional Availability | North America |
| Product Type | Fiber distribution hub |
| Product Series | FDH 3000 |

General Specifications

| | |
|------------------------------------------------|-------------------------|
| Access | Front |
| Cable Type | Dielectric - Loose Tube |
| Color | Putty white |
| Distribution Cables, quantity | 1 |
| Distribution Ports, quantity | 144 |
| Fibers per Distribution Cable, quantity | 144 |
| Fibers per Feeder Cable, quantity | 24 |
| Interface, Input | SC |
| Interface Feature, Input | APC |
| Mounting | Pole |
| Splitter Slots, quantity | 9 |

Dimensions

| | |
|-----------------------|------------------|
| Height | 914.4 mm 36 in |
| Width | 533.4 mm 21 in |
| Depth | 355.6 mm 14 in |
| Cable Length | 30.48 m 100 ft |
| Enclosure Size | Extra small |

Material Specifications

| | |
|----------------------|---------------|
| Finish | Powder coated |
| Material Type | Steel |

FD3-AC144JDRGGBP2P

Environmental Specifications

Environmental Space Above ground

Packaging and Weights

Packaging quantity 1

Packaging Type Pallet

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

