


FST-DRS32-MT

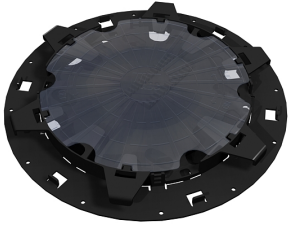

Fiber Optic Round Splice Tray, for 32 mass fusion splices

Product Classification

Regional Availability	EMEA Latin America North America
Product Type	Fiber splice tray
Product Series	FDH 3000 FL2000 NGF OMX

General Specifications

Application	For use with FDH crossconnect cabinets For use with NGF combo blocks For use with OMX splicing blocks
Color	Black
Splicing Capacity, maximum	32
Splicing Type	Mass fusion

Environmental Specifications

Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)
----------------------------	--------------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

