


# L5-CLAMP-2B

---

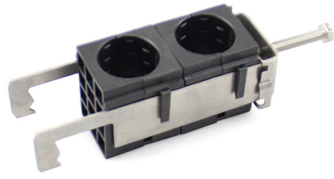

KwikClamp™ Hanger for 7/8 in coaxial cable, double stack; includes hardware

## Product Classification

<b>Product Type</b>	Hanger kit
<b>Product Brand</b>	KwikClamp™
<b>Ordering Note</b>	ANDREW® standard product in Europe, the Middle East, and Africa   Minimum order quantity (MOQ) is 1 box

## General Specifications

<b>Cables per Hanger</b>	1
<b>Color</b>	Black
<b>Hanger Type</b>	KwikClamp™ hanger
<b>Mounting</b>	3–25 mm angle iron   3–25 mm flat plate   Round Member 8–25 mm

## Dimensions

<b>Maximum Stack Height</b>	2
<b>Height</b>	159 mm   6.26 in
<b>Width</b>	45 mm   1.772 in
<b>Length</b>	32 mm   1.26 in
<b>Compatible Diameter, maximum</b>	28 mm   1.102 in
<b>Compatible Diameter, minimum</b>	26 mm   1.024 in
<b>Nominal Size</b>	7/8 in
<b>Hanger Spacing, maximum</b>	1.83 m   6.004 ft

## Electrical Specifications

<b>Return Loss Effect, maximum</b>	0.1 dB
<b>DTF Effect, maximum</b>	0.1 dB

## Material Specifications

<b>Material Type</b>	Engineered plastic   Stainless steel
----------------------	--------------------------------------

# L5-CLAMP-2B

---

## Mechanical Specifications

### Vibration Survival

≥4 hours at resonant frequency

## Environmental Specifications

### Operating Temperature

-40 °C to +70 °C (-40 °F to +158 °F)

### Corrosion Resistance, minimum with no degradation

≥500 hours in salt spray chamber

### Environmental Strength Capability

Five times cable weight

### UV Resistance, minimum with no degradation

≥100 hours exposure in accelerated UV life chamber

## Packaging and Weights

### Height, packed

15.5 cm | 6.102 in

### Width, packed

30.5 cm | 12.008 in

### Length, packed

35.5 cm | 13.976 in

### Included

Hardware

### Packaging quantity

36

### Weight, gross

6.4 kg | 14.11 lb

## Regulatory Compliance/Certifications

### Agency

### Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.andrew.com/ProductCompliance](http://www.andrew.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant



## \* Footnotes

**Maximum Stack Height** Fiber, Hybrid, Power