


MCHD-PK14L4-12-96

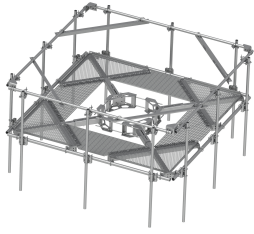

Four-sector HD Platform for 30" to 60" Monopoles, 14ft x 3.5" OD face pipes, 2.88" OD Top Rail, includes (12) 2.88" OD x 96" antenna pipes

Product Classification

Product Type Monopole platform kit

General Specifications

Mounting Monopole, 762–1524 mm (30–60 in) OD

Pipe, quantity 12

Sectors, quantity 4

Dimensions

Height 2,438.4 mm | 96 in

Face Width 4.42 m | 14.5 ft

Width 4,419.6 mm | 174 in

Face Support Pipe Diameter 88.9 mm | 3.5 in

Mounting Diameter, maximum 1,524 mm | 60 in

Mounting Diameter, minimum 762 mm | 30 in

Pipe Outer Diameter 73.025 mm | 2.875 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating Test Method TIA/EIA-222

Packaging and Weights

Included Plain end pipes (12) | Platform | Rail | Ring mount

MCHD-PK14L4-12-96

Packaging quantity 1
Weight, net 1,688.271 kg | 3722 lb