


UGBKIT-0210-T

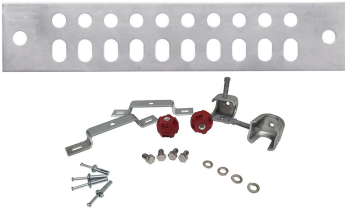

Tinned Copper Ground Buss Bar, 1/4 in x 2 in x 10 in (6.4 mm x 50.8 mm x 254.0 mm)

Product Classification

Product Type	Grounding bar
Ordering Note	CommScope® standard product (Global)

Dimensions

Height	50.8 mm 2 in
Length	254 mm 10 in
Material Thickness	6.35 mm 0.25 in
Hole Size	7/16 in 7/16 in x 5/8 in
Hole Distance, center to center	19.05 mm 0.75 in

Material Specifications

Material Type	Tinned copper
----------------------	---------------

Packaging and Weights

Height, packed	406.4 mm 16 in
Width, packed	381 mm 15 in
Length, packed	63.5 mm 2.5 in
Included	Galvanized angle adapter Grounding bar Insulators Mounting brackets Universal hardware
Packaging quantity	1
Weight, gross	1.81 kg 3.99 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

UGBKIT-0210-T

UK-ROHS

Compliant



Included Products

- GB-HK-DPU – Universal Buss Bar Hardware Kit, UL467 Compliant

GB-HK-DPU



Universal Buss Bar Hardware Kit, UL467 Compliant

Product Classification

Product Type Attachment kit
Ordering Note CommScope® standard product in the United States and Canada

General Specifications

Accessories Grounding Bars

Packaging and Weights

Height, packed 170.18 mm | 6.7 in
Width, packed 129.54 mm | 5.1 in
Length, packed 99.06 mm | 3.9 in
Included Angle adapters | Insulators, Mounting brackets | Universal hardware
Packaging quantity 1
Weight, gross 2.6 kg | 5.732 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

